


B-01-R

Aliases (UDLB000001R0000)

Differential Mode Chokes - Signal, KEMET, BEAD L, Through-Hole, Normal Mode

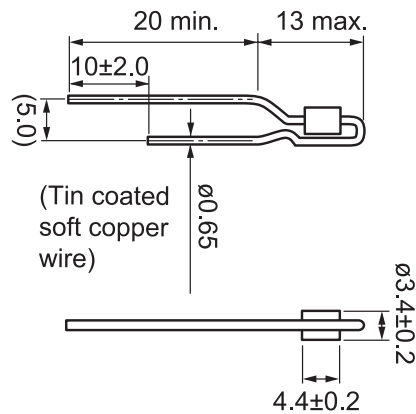

Click [here](#) for the 3D model.

General Information

Series	BEAD L
Style	Through-Hole
RoHS	Yes

Specifications

Temperature Range	-20/+70°C
-------------------	-----------

Dimensions

D	3.4mm +/-0.2mm
L	13mm MAX
LL	20mm MIN
S	5mm NOM
L2	4.4mm +/-0.2mm
F	0.65mm NOM

Packaging Specifications

Packaging	Bulk
Packaging Quantity	100
Typical Component Weight	400 mg

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.