


B-03-RT

Aliases (UDLB00003RT000)

Differential Mode Chokes - Signal, KEMET, BEAD L, Through-Hole, Normal Mode

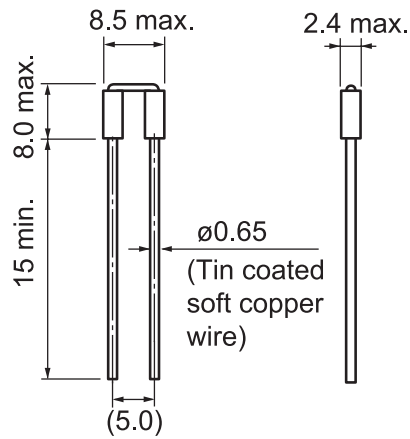

Click [here](#) for the 3D model.

General Information

Series	BEAD L
Style	Through-Hole
RoHS	Yes

Specifications

Temperature Range	-20/+70°C
-------------------	-----------

Dimensions

D	2.4mm MAX
L	8.5mm MAX
W	8mm MAX
LL	15mm MIN
S	5mm NOM
F	0.65mm NOM

Packaging Specifications

Packaging	T&R
Packaging Quantity	2000
Typical Component Weight	300 mg

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.