


GL-2060FV-10

Aliases (UNFGL2060FV10X)

Obsolete

KEMET, GL, EMI/RFI Filters, Noise Suppression, 250 VAC

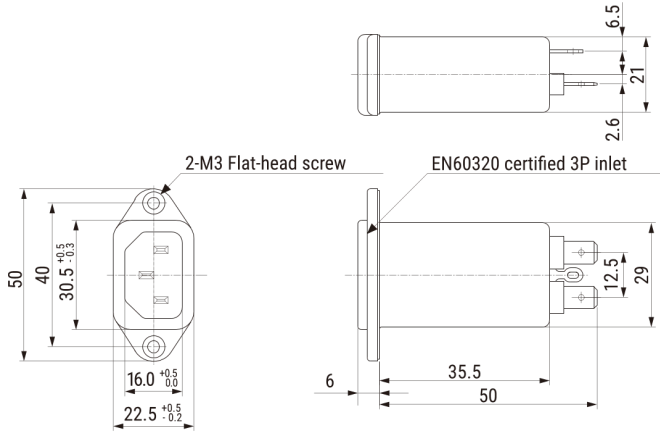

Click [here](#) for the 3D model.

Dimensions

L	56mm NOM
W	50mm NOM
H	22.5mm -0.2/+0.5

Packaging Specifications

Packaging	Tray, Box
Packaging Quantity	25
Typical Component Weight	40 g

General Information

Series	GL
Style	Metal Box
Description	Noise Filters
RoHS	Yes
Qualifications	UL, CSA, TUV
Notes	Last time buy due: May 31, 2024.
Miscellaneous	30 K Self-Temperature Rise Max.

Specifications

Voltage AC	250 VAC
Voltage	1500 VAC Withstanding Voltage 1 Min. Line to Ground
Rated Current	6 A (AC/DC)
Rated Temperature	55°C
Temperature Range	-25/+55°C
Leakage Current	0.5 mA MAX (250 V 60 Hz)
ESR	300 MOhms MIN Insulation 500 VDC 1 Min. Line To Ground