


## GL-2100M

Aliases (UNFGL2100MXXXX)

Obsolete

EMI Filters, KEMET, GL, Metal Box, Noise Suppression

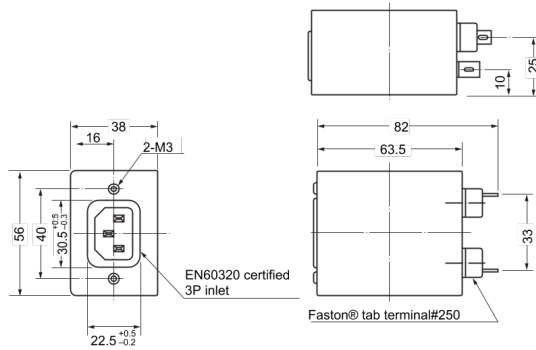

Click [here](#) for the 3D model.

### Dimensions

L	82mm NOM
W	56mm NOM
H	38mm NOM
Lead	Screw Terminals

### Packaging Specifications

Packaging	Tray, Box
Packaging Quantity	8
Typical Component Weight	210 g

### General Information

Series	GL
Style	Metal Box
Description	Noise Filters
RoHS	With Exemptions
Qualifications	UL, CSA, TUV
Miscellaneous	30 K Self-Temperature Rise Max.
Lead	Screw Terminals
Terminal Type	Screw

### Specifications

Voltage AC	250 VAC
Voltage	1500 VAC Withstanding Voltage 1 Min. Line to Ground
Rated Current	10 A (AC/DC)
Ripple Current	10 A (AC/DC)
Rated Temperature	55°C
Temperature Range	-25/+55°C
Leakage Current	0.5 mA
ESR	300 MOhms MIN Insulation 500 VDC 1 Min. Line To Ground