


## MA-2053

Aliases (UNFMA2053XXXXX)

Obsolete

EMI Filters, KEMET, MA, Plastic Box, Noise Suppression

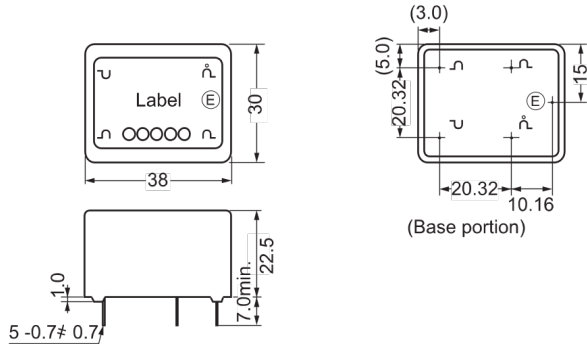

Click [here](#) for the 3D model.

### Dimensions

L	38mm NOM
W	30mm NOM
H	22.5mm NOM

### Packaging Specifications

Packaging	Tray, Box
Packaging Quantity	50
Typical Component Weight	30 g

### General Information

Series	MA
Style	Plastic Box
Description	Noise Filters
RoHS	Yes
Qualifications	UL, CSA, TUV
Miscellaneous	30 K Self-Temperature Rise Max.

### Specifications

Voltage AC	250 VAC
Voltage	1500 VAC Withstanding Voltage 1 Min. Line to Ground
Rated Current	5 A (AC/DC)
Ripple Current	5 A (AC/DC)
Temperature Range	-25/+55°C
Leakage Current	0.75 mA
ESR	300 MOhms MIN Insulation 500 VDC 1 Min. Line To Ground