


SBC4-102-291

Aliases (UPIN4102291000)

KEMET, SBC4, Ferrite, 10%, 1000 uH, 9mm, 5mm

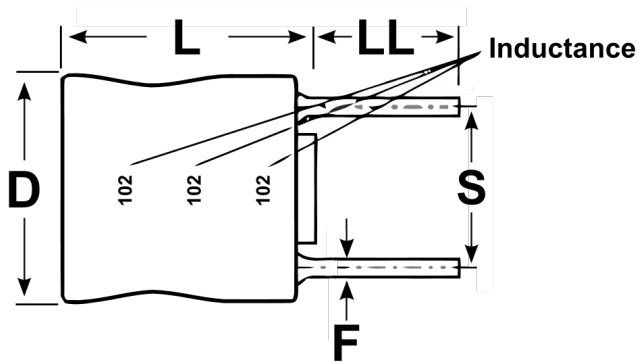

Click [here](#) for the 3D model.

Dimensions

D	9mm MAX
L	14.5mm MAX
S	5mm +/-0.5mm
F	0.6mm NOM

Packaging Specifications

Typical Component Weight	2.6 g
Packaging	Bulk
Packaging Quantity	4000

General Information

Series	SBC4
Style	Through-Hole Drum
Core	Ferrite
Description	Radial Leaded, Ferrite Power Inductors
Features	DC-DC Converters, Nickel-Zinc (NiZn) Ferrite Core
RoHS	Yes
Lead	Wire Leads
Miscellaneous	Pin Lead Terminal

Specifications

Inductance	1000 uH
Inductance Tolerance	10%
Temperature Range	-20/+105°C
Shielded	No
Current	0.29 Amps
DC Resistance	2.15 Ohms