


## SBC8-100-692

Aliases (UPIN8100692000)

KEMET, SBC8, Ferrite, 20%, 10 uH, 15mm, 10mm

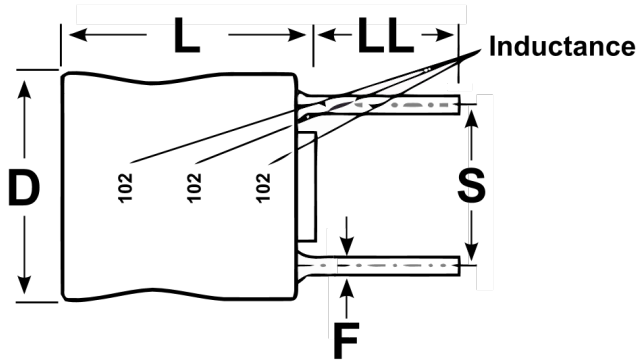

Click [here](#) for the 3D model.

### Dimensions

D	15mm MAX
L	19mm MAX
S	10mm NOM
F	1mm NOM

### Packaging Specifications

Typical Component Weight	10.257 g
Packaging	Bulk
Packaging Quantity	900

### General Information

Series	SBC8
Style	Through-Hole Drum
Core	Ferrite
Description	Radial Leaded, Ferrite Power Inductors
Features	DC-DC Converters, Nickel-Zinc (NiZn) Ferrite Core
RoHS	Yes
Lead	Wire Leads
Miscellaneous	Soft Lead Terminal

### Specifications

Inductance	10 uH
Inductance Tolerance	20%
Temperature Range	-20/+105°C
Shielded	false
Current	6.9 Amps
DC Resistance	0.02 Ohms