


SBT-0140W

Aliases (UDLSBTW0140W00)

KEMET, SBT-01W, DC Line Filters, Common Mode, 40 uH, 35%

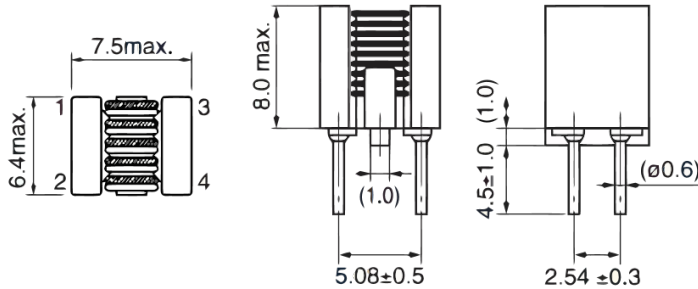

Click [here](#) for the 3D model.

Dimensions

| | |
|----|-----------------|
| L | 7.5mm MAX |
| W | 6.4mm MAX |
| H | 8mm MAX |
| LL | 4.5mm +/-1mm |
| S | 5.08mm +/-0.5mm |

Packaging Specifications

| | |
|--------------------------|-----------|
| Packaging | Bulk, Box |
| Packaging Quantity | 100 |
| Typical Component Weight | 500 mg |

General Information

| | |
|---------------|-----------------------------|
| Series | SBT-01W |
| Style | Through-Hole |
| RoHS | Yes |
| Miscellaneous | Inductance: 70mAmps (1kHz). |

Specifications

| | |
|----------------------|----------------|
| Voltage DC | 50 VDC |
| Inductance | 40 uH |
| Inductance Tolerance | 35% |
| Temperature Range | -25/+70°C |
| DC Resistance | 40 mOhms (MAX) |