


SC-05-D150H

Aliases (UALSC05D150H00)

KEMET, SC-D, AC Line Filters, Common Mode, 1.5 mH

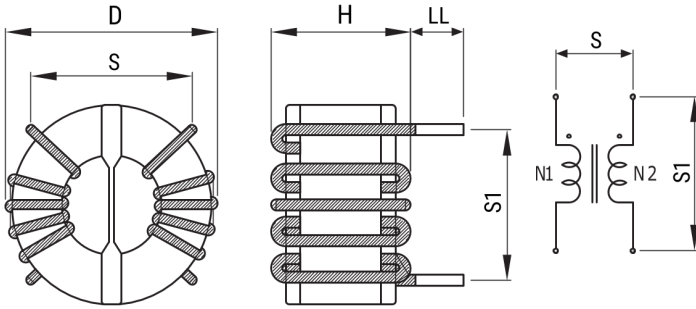

Click [here](#) for the 3D model.

Dimensions

D	48mm MAX
H	25mm MAX
LL	15mm +/-2mm
S	15mm
S1	40mm
Wire Size	0.9mm

Packaging Specifications

Packaging	Tray
Packaging Quantity	90
Typical Component Weight	89.2 g

General Information

Series	SC-D
Style	Through-Hole
RoHS	Yes
Notes	Lead Spacing (S/S1) Are For Reference Only.
Miscellaneous	Temperature Rise Maximum: 60 K.
Core	Ni-Zn Ferrite

Specifications

Voltage AC	250 VAC
Inductance	1500 uH
Current	5 A
Temperature Range	-40/+120°C
DC Resistance	90 mOhms