


## SC-20-400

Aliases (UALSC204000000)

Common Mode Chokes - Power, KEMET, SC, Through-Hole, Common Mode, 4 mH

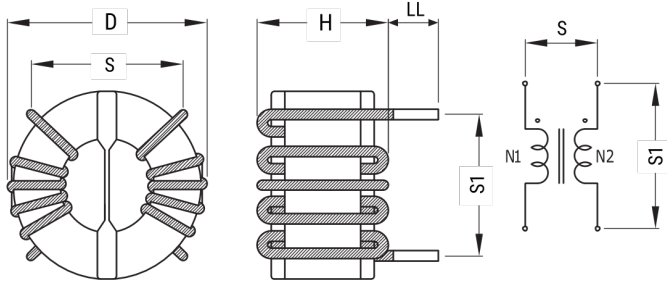

Click [here](#) for the 3D model.

### Dimensions

D	63mm MAX
H	35mm MAX
LL	15mm +/-2mm
S	20mm
S1	50mm
Wire Size	2.3mm

### Packaging Specifications

Packaging	Tray
Packaging Quantity	60
Typical Component Weight	205 g

### General Information

Series	SC
Style	Through-Hole
RoHS	Yes
Notes	Lead Spacing (S/S1) Are For Reference Only.
Miscellaneous	Temperature Rise Maximum: 55 K.
Core	Mn-Zn Ferrite

### Specifications

Voltage AC	250 VAC
Inductance	4 mH (1 kHz)
Current	20 A
Temperature Range	-40/+105°C
DC Resistance	13 mOhms