


SCR25B-105-1R3A035JH

Aliases (UALE11R3A035JH)

KEMET, SCR25, AC Line Filters, Common Mode, 3.5 mH

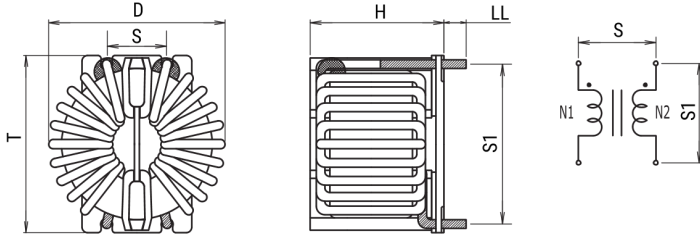

Click [here](#) for the 3D model.

Dimensions

| | |
|-----------|------------|
| D | 35mm MAX |
| T | 33mm MAX |
| H | 26mm MAX |
| LL | 5mm +/-2mm |
| S | 11mm NOM |
| S1 | 29mm NOM |
| Wire Size | 1.3mm |

Packaging Specifications

| | |
|--------------------------|------|
| Packaging | Tray |
| Packaging Quantity | 140 |
| Typical Component Weight | 49 g |

General Information

| | |
|---------------|------------------------------|
| Series | SCR25 |
| Style | Through-Hole |
| Features | High Impedance, Space Saving |
| RoHS | Yes |
| Miscellaneous | 70 (K) Temperature Rise Max. |
| Core | Mn-Zn Ferrite |

Specifications

| | |
|-------------------|------------|
| Voltage AC | 500 VAC |
| Inductance | 3.5 mH |
| Current | 10.5 A |
| Temperature Range | -40/+120°C |
| DC Resistance | 17 mOhms |