


SNG-19A-080

Aliases (UALSNG19A08000)

Obsolete

KEMET, SNG, AC Line Filters, Ground Wire, 0.08 mH, -30/+50%

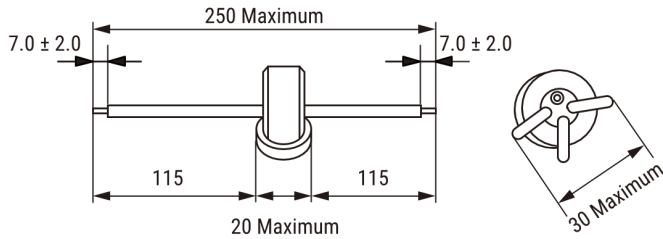

Click [here](#) for the 3D model.

Dimensions

D	30mm MAX
L	20mm MAX
LL	115mm NOM
L2	250mm MAX
Wire Size	UL1015 AWG16

Packaging Specifications

Packaging	Bulk
Packaging Quantity	250
Typical Component Weight	19 g

General Information

Series	SNG
Style	Through-Hole
RoHS	Yes
Qualifications	TUV
Notes	Last time buy due: May. 31, 2024.
Core	Mn-Zn Ferrite or Ni-Zn Ferrite

Specifications

Voltage AC	250 VAC
Voltage DC	250 VDC
Inductance	80 uH (160 kHz)
Inductance Tolerance	-30/+50%
Temperature Range	-40/+105°C
DC Resistance	10 mOhms