


T354A185J025AT7305

Aliases (T354A185J025ATAMMO)

T354, Tantalum, MnO2 Tantalum, Commercial Grade, 1.8 uF, 5%, 25 VDC, Radial, Solid Tantalum, Conformal, Dipped, 6.35mm

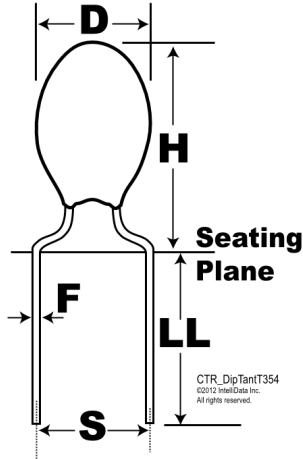

Click [here](#) for the 3D model.

Dimensions

D	4.5mm
H	8.6mm
S	6.35mm +/-0.38mm
LL	4.75mm +/-0.81mm
F	0.5mm +/-0.05mm

Packaging Specifications

Packaging	Ammo
Packaging Quantity	2500

General Information

Series	T354
Dielectric	MnO2 Tantalum
Style	Radial
Description	Radial, Solid Tantalum, Conformal, Dipped
Features	Low Leakage
RoHS	Yes
Termination	Tin
AEC-Q200	No
Construction	Conformal
Notes	Longest Lead Is Positive.

Specifications

Capacitance	1.8 uF
Capacitance Tolerance	5%
Voltage DC	25 VDC (85C), 16 VDC (125C), 0.25 VDC (125C Reverse)
Temperature Range	-55/+125°C
Dissipation Factor	5%
Leakage Current	0.5 uA