


## VU-215F

Aliases (UNFVU215FXXXXX)

Obsolete

KEMET, VU, EMI/RFI Filters, Noise Suppression, 250 VAC, 15 A

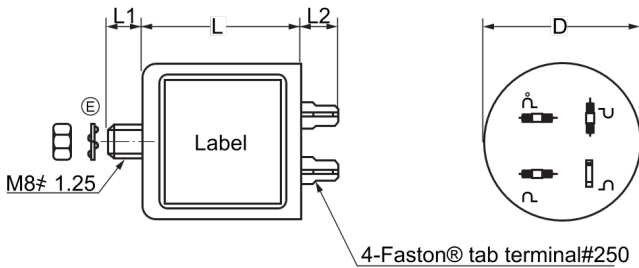

Click [here](#) for the 3D model.

### Dimensions

D	38mm NOM
L	50mm NOM
L1	12mm NOM
L2	13mm NOM
Lead	Fast On

### Packaging Specifications

Packaging	Tray, Box
Packaging Quantity	30
Typical Component Weight	130 g

### General Information

Series	VU
Style	Metal Cylinder
Description	Noise Filters
RoHS	With Exemptions
Qualifications	UL, CSA
Notes	Last time buy due: May 31, 2024.
Miscellaneous	40 K Self-Temperature Rise Max.
Lead	Fast On
Terminal Type	Faston

### Specifications

Voltage AC	250 VAC
Voltage	1500 VAC Withstanding Voltage 1 Min. Line to Ground
Rated Current	15 A (AC/DC)
Ripple Current	15 A (AC/DC)
Temperature Range	-25/+55°C
Leakage Current	1 mA MAX (250 V 60 Hz)
ESR	300 MOhms MIN Insulation 500 VDC 1 Min. Line To Ground