


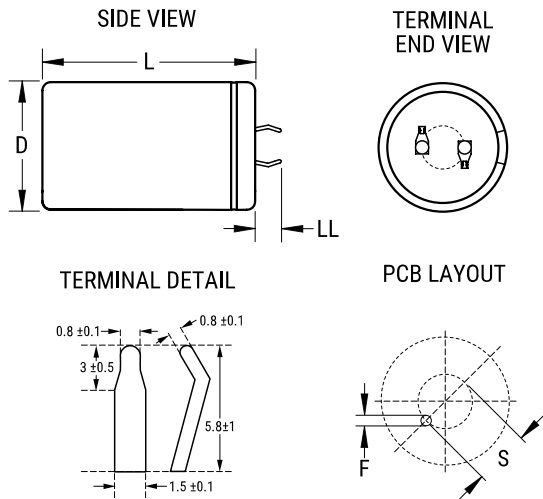

Click [here](#) for the 3D model.

#### General Information

|             |                                |
|-------------|--------------------------------|
| Series      | ELH                            |
| Dielectric  | Aluminum Electrolytic          |
| Description | Snap-In, Aluminum Electrolytic |
| RoHS        | Yes                            |
| Lead        | 2 Pin                          |
| AEC-Q200    | No                             |

#### Specifications

|                    |                         |
|--------------------|-------------------------|
| Capacitance        | 2,700 uF                |
| Tolerance          | 20%                     |
| Voltage DC         | 63 VDC, 79 VDC (Surge)  |
| Temperature Range  | -40/+85°C               |
| Rated Temperature  | 85°C                    |
| Life               | 2000 Hrs                |
| Dissipation Factor | 25% 120Hz 20C           |
| ESR                | 0.1229 Ohms (120Hz 20C) |
| Ripple Current     | 2.5 Amps (120Hz 85C)    |
| Leakage Current    | 3 mA (5min 20°C)        |

#### Dimensions

|    |                |
|----|----------------|
| D  | 30mm +1mm      |
| L  | 25mm +2mm      |
| S  | 10mm +/-0.5mm  |
| LL | 4mm +/-1mm     |
| F  | 1.5mm +/-0.1mm |

#### Packaging Specifications

|                    |           |
|--------------------|-----------|
| Packaging          | Bulk, Bag |
| Packaging Quantity | 200       |