


## FLLE2010APMD

Aliases (LLE2010APMD)

KEMET, FLLE2-P, EMI/RFI Filters, Noise Suppression, 300 VAC, 300 V, 10 A, 51x45x19mm

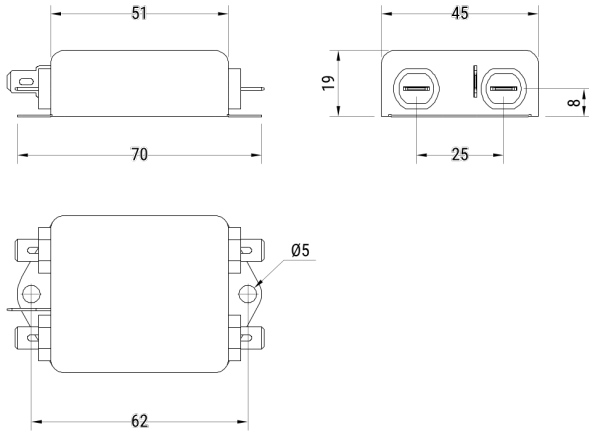

Click [here](#) for the 3D model.

### Dimensions

|   |          |
|---|----------|
| L | 51mm MIN |
| W | 45mm MIN |
| H | 19mm MIN |

### Packaging Specifications

|                          |       |
|--------------------------|-------|
| Packaging                | Bulk  |
| Packaging Quantity       | 1     |
| Typical Component Weight | 100 g |

### General Information

|                |                                     |
|----------------|-------------------------------------|
| Series         | FLLE2-P                             |
| Style          | Chassis Mount                       |
| Description    | Single Phase, Chassis Mount Filters |
| Features       | Single Phase, Medical               |
| Phase          | Single-phase                        |
| RoHS           | Yes                                 |
| Qualifications | IEC/EN 60939, UL, CSA               |
| Terminal Type  | Wire                                |

### Specifications

|                            |               |
|----------------------------|---------------|
| Voltage AC                 | 300 VAC       |
| Voltage DC                 | 300 VDC       |
| Rated Frequency            | 50-60 Hz      |
| Rated Current              | 10 A          |
| Rated Temperature          | 40°C          |
| Temperature Range          | -25/+100°C    |
| Climate Category           | 25/100/21     |
| Leakage Current            | 0.37 mA (MAX) |
| Test Voltage DC (P/N to E) | 2250 VDC      |
| Test Voltage DC (P to N)   | 1300 VDC      |